

PRODUCT INFORMATION PACKET



Model No: 332
Catalog No: 332

OEM Replacement Motor, 1/20-1/30 HP, 1 Ph, 60 Hz, 115 V, 1000 RPM, 2 Speed, 4.4" Diameter, TEAO



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.
©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Output HP	1/20-1/30 Hp	Output KW	0.04 kW
Frequency	60 Hz	Voltage	115 V
Current	2.2/1.1 A	Speed	1000 rpm
Service Factor	1	Phase	1
Duty	Continuous Air Over	Insulation Class	A
Frame	4.4	Enclosure	Totally Enclosed Air Over
Thermal Protection	Automatic	Ambient Temperature	40 °C
UL	Recognized	CSA	N
CE	N	Number of Speeds	2

Technical Specifications

Electrical Type	Shaded Pole	Starting Method	Across The Line
Poles	6	Rotation	Clockwise Shaft End
Mounting	Resilient Base	Motor Orientation	Horizontal
Drive End Bearing	Sleeve	Opp Drive End Bearing	Sleeve
Frame Material	Rolled Steel	Shaft Type	Flat
Overall Length	8.42 in	Shaft Diameter	0.375 in
Shaft Extension	3/8 X 2 7/8 in		
Outline Drawing	CA3J104-S01		

 
This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/29/2022

REGAL

PROPRIETARY INFORMATION NOTICE:

THIS DOCUMENT IS AND CONTAINS CONFIDENTIAL TRADE SECRET INFORMATION OF THE COMPANY AND REMAINS THE PROPERTY OF THE COMPANY AND IS TO BE RETURNED UPON REQUEST. NEITHER IT NOR THE INFORMATION IT CONTAINS MAY BE REPRODUCED OR DISCLOSED TO PERSONS NOT HAVING A NEED-TO-KNOW CONSISTENT WITH THE PURPOSE OF THE LOAN OF THE DOCUMENT.

THIRD ANGLE PROJECTION



CA3J104N#


STOCK NO.: 332

Gainsborough, Lincs DN21 1XU. UK
Tel.: +44(0)1427 614141 Fax.: +44(0)1427 617513

CUSTOMER IS SOLELY RESPONSIBLE FOR MOTOR PERFORMANCE AND SUITABILITY IN APPLICATIONS FOR CUSTOMER'S USES.

ENDPLAY .005-.040

TOL.±.015

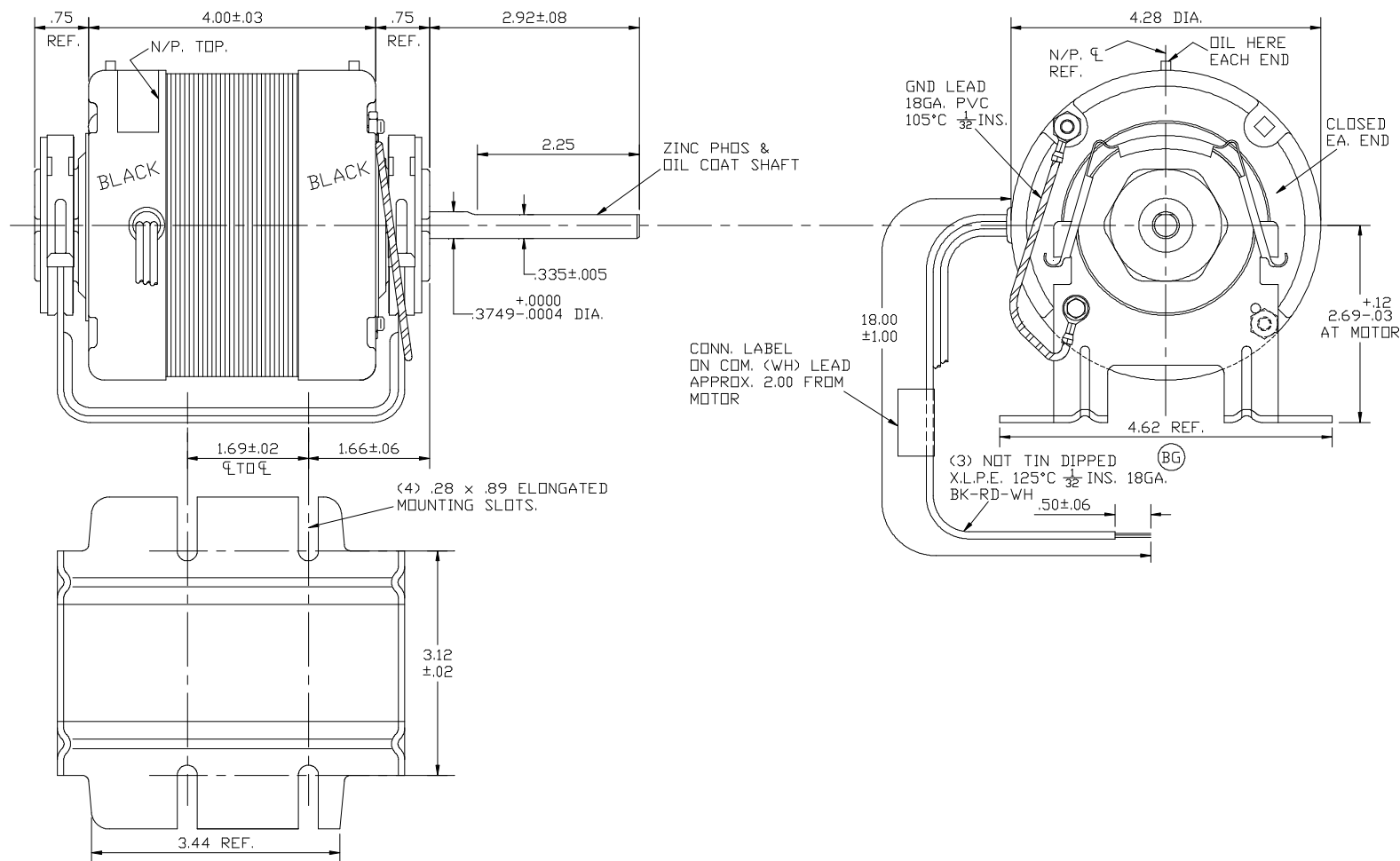

ALL DIMENSIONS IN INCHES UNLESS STATED.

ELEC. AS SAMPLE P03175

ROTATION CCWLE-CWSE

ISSUE 'BL' 16 JUL 12

REGAL - LAVERGNE

BL

NAMEPLATE DATA:



SER DDDYYGB-sonum-J104 MOD CA3J104N# STOCK No 332
115V 60HZ 2.2A 1000RPM 1PH CONT A.O.
WH.COM. BK-HIGH 2.2A 1/20HP. RD-LOW 1.1A 1/30HP.
THERMALLY PROTECTED. MADE IN UK. WARRANTY VOID IF REMOVED