

PRODUCT INFORMATION PACKET



Model No: 363

Catalog No: 363

Fan Coil & Air Conditioner Motor, 1/20-1/30-1/40-1/60 HP, 1 Ph, 60 Hz, 115 V, 1550 RPM, 4 Speed,
4.4" Diameter, OPEN



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.
©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Output HP	1/20-1/30-1/40-1/60 Hp	Output KW	0.04 kW
Frequency	60 Hz	Voltage	115 V
Current	1.8/1.3/.95/.70 A	Speed	1550 rpm
Service Factor	1	Phase	1
Duty	Continuous Air Over	Insulation Class	B
Frame	4.4	Enclosure	Open Enclosed
Thermal Protection	Automatic	Ambient Temperature	40 °C
UL	Recognized	CSA	Y
CE	N	Number of Speeds	4

Technical Specifications


Electrical Type	Shaded Pole	Starting Method	Across The Line
Poles	4	Rotation	Clockwise Lead End
Mounting	Extended Studs	Motor Orientation	Horizontal
Drive End Bearing	Sleeve	Opp Drive End Bearing	Sleeve
Frame Material	Rolled Steel	Shaft Type	Flat
Overall Length	18.25 in	Shaft Diameter	0.375 in
Shaft Extension	7 1/2 x 3/8 X 7 1/2 in		
Outline Drawing	CA2F043-S01		

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/29/2022

(REF. 63T457J-1)

BK HIGH 1.8A 1/20HP
YE MED HI 1.3A 1/30HP
BU MED .95A 1/40HP
RD LOW .70A 1/60HP
WH COM

END PLAY .04[1.0] MAX.

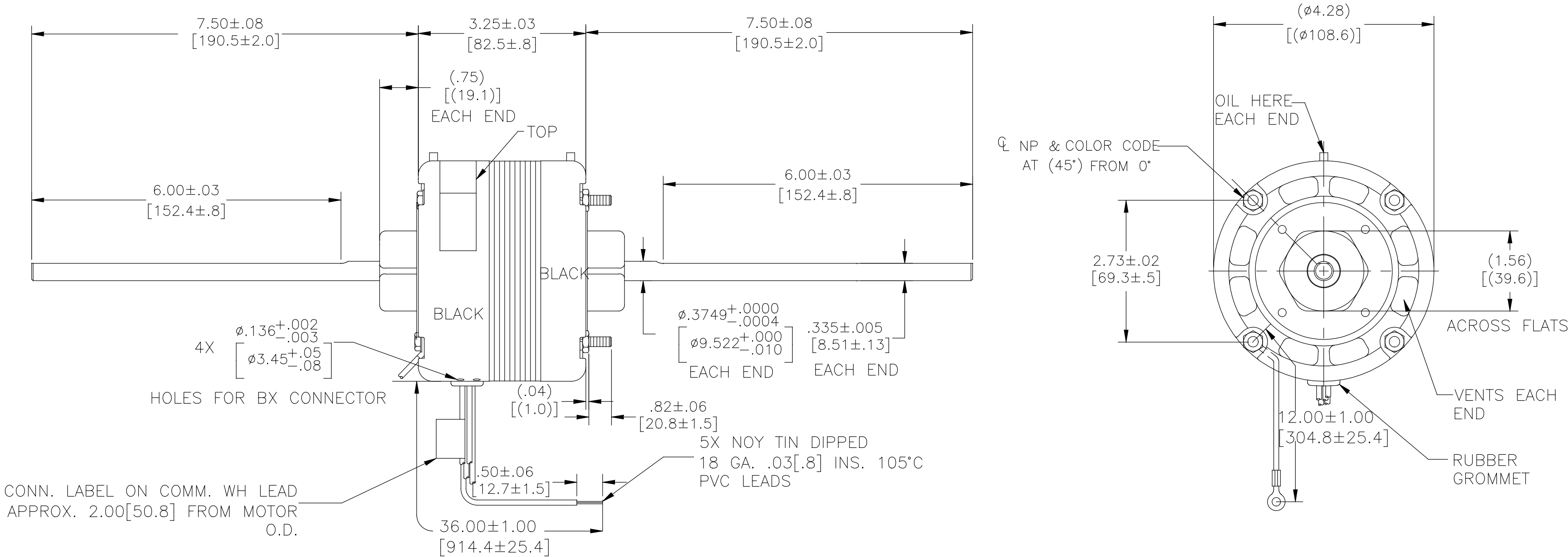

NAMEPLATE DATA:
(REF. 63T444J-1)



Tipp City, OH

THERMALLY PROTECTED

SER. DATE, PLT MOD CA2F043N# STOCK NO 363
115V 60HZ 1.8A 1550RPM 1PH CONT A.O.
ASSEMBLED IN MEXICO



CONN. LABEL
63T473J-9

ELECTRICALLY PER
SAMPLE S-371C-1

CWLE

DRAWING REVISION CF	REVISION BY G.ZHAO	DATE 06-13-2017	TOLERANCES UNLESS OTHERWISE SPECIFIED DEC. INCH mm ANGLE .X ±0.1 [±0.5] ±0.5° .XX ±0.02 [±0.13] .XXX ±0.005 [±0.013] .XXXX ±0.0005 [±0.0013] REMOVE BURRS & BREAK SHARP EDGES .003/.015 [0.08/.38] CORNER FILLETS .02 [5] MACHINED SURFACES INCH 125/ mm 3.2/ mm SHOWN IN [BRACKETS]	DRAWN BY: JAB	 Regal Beloit America, Inc.			
ECO-0124906	APPROVED BY DURAN	DATE 06-13-2017		DATE: -				
ECO DESCRIPTION SEE ECO				APPROVED BY: -	DESCRIPTION MODEL-SFHP-4.3 OUTLINE			
COPYRIGHT REGAL BELOIT AMERICA, INC. ALL RIGHTS RESERVED. PROPRIETARY AND CONFIDENTIAL INFORMATION - THIS DOCUMENT IS THE PROPERTY OF REGAL BELOIT AMERICA, INC. (OWNER) AND CONTAINS OWNER'S PROPRIETARY INFORMATION. ANY PERSON, CORPORATION OR OTHER FIRM RECEIVING IT IS DEEMED, BY RECEIVING IT, TO AGREE THAT IT, AND/OR ANY PART OF IT, SHALL NOT BE DISCLOSED TO ANY PERSON, CORPORATION OR OTHER ENTITY, DUPLICATED, AND/OR USED, EXCEPT AS EXPRESSLY APPROVED IN ADVANCE BY OWNER. THIS DOCUMENT SHALL BE RETURNED TO OWNER UPON REQUEST. IT MAY BE SUBJECT TO CERTAIN RESTRICTIONS UNDER APPLICABLE EXPORT CONTROL LAWS AND REGULATIONS.				DATE: -	REFERENCE -	MATERIAL -	PROCESS/FINISH -	
				THIRD ANGLE PROJECTION			SIZE DWG NO C CA2F043	SHEET 1