

PRODUCT INFORMATION PACKET



Model No: 394

Catalog No: 394

OEM Replacement Motor, 1/15 HP, 1 Ph, 60 Hz, 115 V, 1050 RPM, 1 Speed, 4.4" Diameter, OAO



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Output HP	1/15 Hp	Output KW	0.05 kW
Frequency	60 Hz	Voltage	115 V
Current	2.2 A	Speed	1050 rpm
Service Factor	1	Phase	1
Duty	Continuous Air Over	Insulation Class	B
Frame	4.4	Enclosure	Open Air Over
Thermal Protection	Automatic	Ambient Temperature	40 °C
UL	No	CSA	N
CE	Y	Number of Speeds	1

Technical Specifications

Electrical Type	Shaded Pole	Starting Method	Across The Line
Poles	6	Rotation	Clockwise Shaft End
Mounting	Extended Studs	Motor Orientation	Horizontal
Drive End Bearing	Ball	Opp Drive End Bearing	Ball
Frame Material	Rolled Steel	Shaft Type	Flat
Overall Length	7.92 in	Shaft Diameter	0.375 in
Shaft Extension	3/8 X 3 in		
Outline Drawing	CB3J015-S01		

 
This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/29/2022



Gainsborough, Lincs DN21 1XU. UK
Tel.: +44(0)1427 614141 Fax.: +44(0)1427 617513

PROPRIETARY INFORMATION NOTICE:
THIS DOCUMENT IS AND CONTAINS CONFIDENTIAL TRADE SECRET INFORMATION OF THE COMPANY AND REMAINS THE PROPERTY OF THE COMPANY AND IS TO BE RETURNED UPON REQUEST. NEITHER IT NOR THE INFORMATION IT CONTAINS MAY BE REPRODUCED OR DISCLOSED TO PERSONS NOT HAVING A NEED-TO-KNOW CONSISTENT WITH THE PURPOSE OF THE LOAN OF THE DOCUMENT.

THIRD ANGLE PROJECTION




CB3J015N"

STOCK NO.: 394

CUSTOMER IS SOLELY RESPONSIBLE FOR MOTOR PERFORMANCE AND SUITABILITY IN APPLICATIONS FOR CUSTOMER'S USES.

BRG PRELOAD (OLE)
(CUSHIONED)

TOL. ±.015

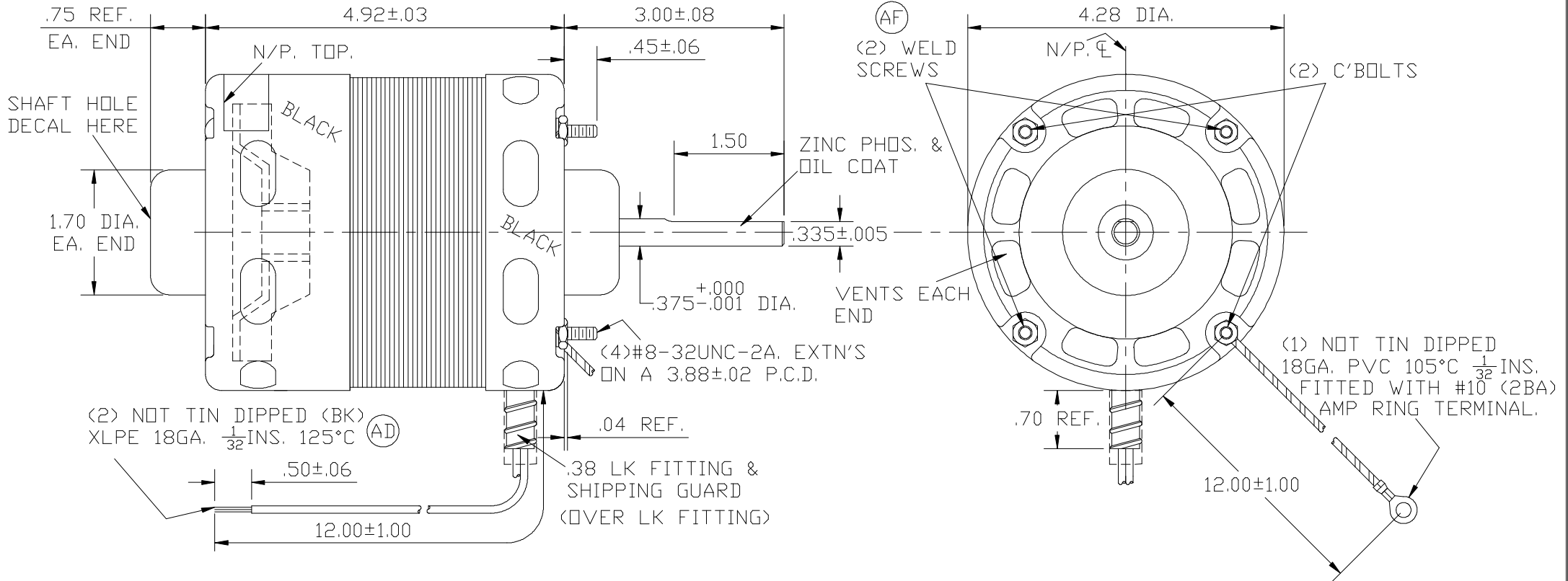

ALL DIMENSIONS IN INCHES UNLESS STATED.

ROTATION CWLE-CWSE

ISSUE 'AH' 16 JUL 12

REGAL - LAVERGNE

(AH)

NAMEPLATE DATA:



SER DDDYYGB-sonum-J015 MOD CB3J015N" STOCK No 394
115V 60HZ 2.2A 1/15HP 1050RPM 1PH CLASS B INS.
BB. MAX AMB. 40°C CONT A.O.
THERMALLY PROTECTED. MADE IN UK. WARRANTY VOID IF REMOVED