


PRODUCT INFORMATION PACKET



Model No: 546

Catalog No: 546

Fan Coil & Air Conditioner Motor, 1/20, 1/30, 1/50, 1/75 HP, 1 Ph, 60 Hz, 115 V, 1075 RPM, 4 Speed,
42 Frame, OAO

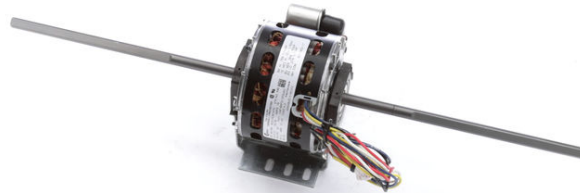

Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

©2023 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Phase	1	Output HP	1/20, 1/30, 1/50, 1/75 Hp
Output KW	0.04 kW	Voltage	115 V
Speed	1075 rpm	Service Factor	1
Frame	42	Enclosure	Open Air Over
Thermal Protection	Automatic	Ambient Temperature	40 °C
Frequency	60 Hz	Current	.78 A
Duty	Continuous Air Over	Insulation Class	A
UL	Recognized	CSA	Y
CE	N	Number of Speeds	4

Technical Specifications

Electrical Type	Permanent Split Capacitor	Starting Method	Across The Line
Poles	6	Rotation	Clockwise Lead End
Mounting	Resilient Base	Motor Orientation	Horizontal
Drive End Bearing	Sleeve	Opp Drive End Bearing	Sleeve
Frame Material	Rolled Steel	Shaft Type	Flat
Overall Length	24.75 in	Frame Length	2.92 in
Shaft Diameter	0.500 in	Shaft Extension	10.6X.5X10.6 in
Outline Drawing	546-S01		

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:04/24/2023

