

PRODUCT INFORMATION PACKET



Model No: 9724
Catalog No: 9724

MULTIFIT® Condenser Fan Motor, 1/4-1/5-1/6 HP, 1 Ph, 60 Hz, 208-230 V, 1625 RPM, 1 Speed, 42 Frame,
TEAO



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.
©2024 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Phase	1	Output HP	1/4-1/5-1/6 Hp
Output KW	0.19 kW	Voltage	208-230 V
Speed	1625 rpm	Service Factor	1.0
Frame	42	Enclosure	Totally Enclosed Air Over
Thermal Protection	Automatic	Ambient Temperature	70 °C
Frequency	60 Hz	Current	1.7 A
Duty	Air Over	Insulation Class	F
UL	Recognized	CSA	Y
CE	N	Number of Speeds	1


Technical Specifications

Electrical Type	Permanent Split Capacitor	Starting Method	Across The Line
Poles	4	Rotation	Reversible
Mounting	Extended Studs	Motor Orientation	Any
Drive End Bearing	Ball	Opp Drive End Bearing	Ball
Frame Material	Rolled Steel	Shaft Type	Flat
Overall Length	7.50 in	Frame Length	4.77 in
Shaft Diameter	0.500 in	Shaft Extension	3.0 in
Outline Drawing	9724_FA		

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:02/07/2024

GENERAL INFORMATION:

SHAFT RUNOUT: .001 [.025] T.I.R. PER INCH LENGTH OF EXTENSION
BEARINGS: BALL (L. E. PRELOAD)
MOUNTING POSITION: ALL ANGLE

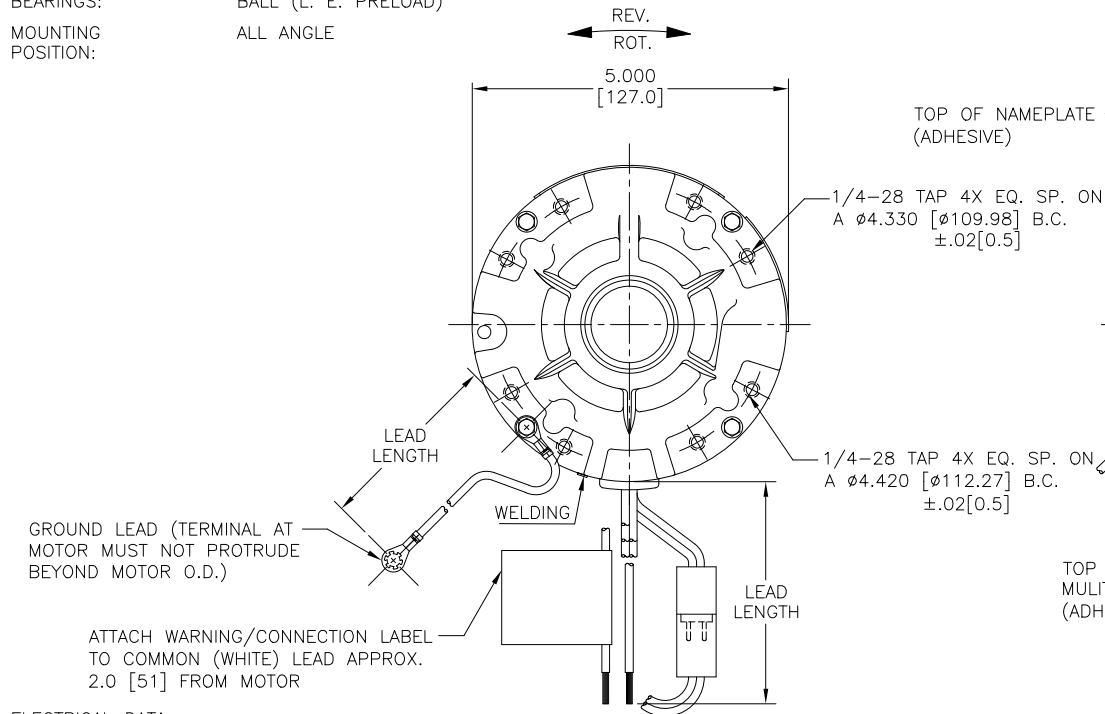


ELECTRICAL DATA:

OVERLOAD PROTECTOR: AUTOMATIC RESET (7AM033A5-481-8C)
LEADS: NO. 18 GA., .03 [.8] THK. XLP 125°C INSUL.
REVERSING PLUGS: NO. 18 GA., .03 [.8] THK. XLP 125°C INSUL.
GROUND LEAD: NO. 18 GA., .03 [.8] THK. (GREEN) INSUL.

TOP OF NAMEPLATE (ADHESIVE)

TOP OF STICKER MULTIFIT (ADHESIVE)

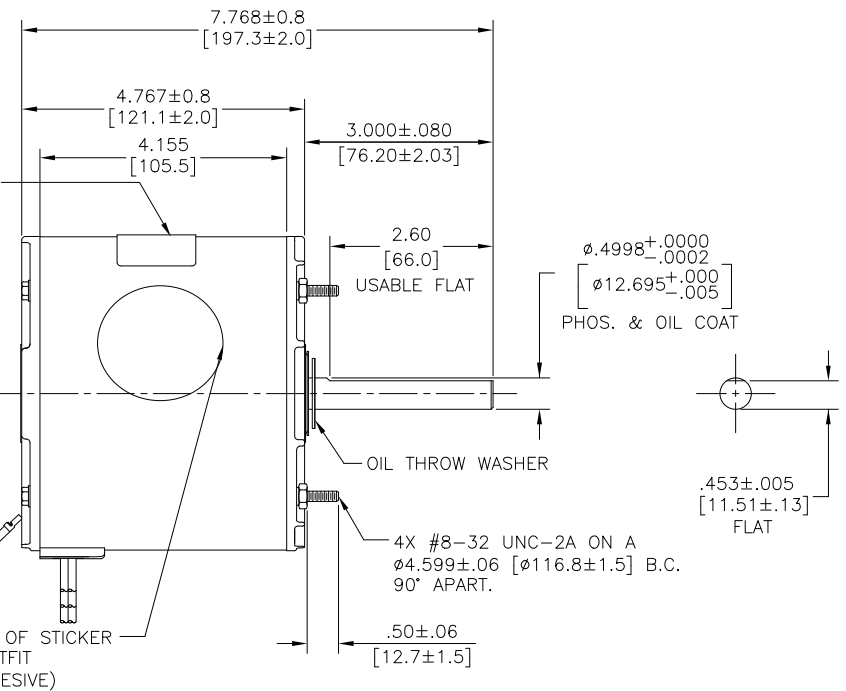

NOTE:

- 1) 4X SHOULDER STUDS 631585-062, 8X PLUGS PLU213, 4X HEX NUTS N238P15B9 AND 1 INSTALLATION MANUAL 2516557-001_FA TO BE PUT IN A POLY BAG AND PACKED WITH EACH MOTOR.
- 2) 1 INSTRUCTION SHEET 2515675-001 TO BE PACKED ALONG THE SIDE OF EACH MOTOR, AND NOT INSIDE THE POLYBAG.
- 3) ALL LABEL READABLE FROM LE SIDE.

MAIN FRAME - OLE	ENCLOSED
END FRAME - OLE	ENCLOSED
MAIN FRAME - LE	ENCLOSED
END FRAME - LE	ENCLOSED
ENCLOSURE	

GREEN (GROUND)	11.0/13.0 [279/330]	#10 EYELET
BLACK/WHITE	3.0/5.0 [76/127]	REVERSING PLUGS
BROWN	36.0/39.0 [914/991]	.60 [15.2] SKIN
WHITE	36.0/39.0 [914/991]	.60 [15.2] SKIN
BLACK	36.0/39.0 [914/991]	.60 [15.2] SKIN
COLOR	LENGTH	TERMINAL OR STRIP LENGTH

REF. DRG.DF2H7016/SM21-251

CONNECTION DIAGRAM



THERMALLY PROTECTED
INS CL F AO

STK. NO. 9724


← ROTATION →

RPM 1625 HZ 60 PH 1 CAP 5 MFD/440 VAC

BRG BALL AMPS 1.7 HP 1/4, 1/5, 1/6

MADE IN INDIA

5KCP29KGE1004S

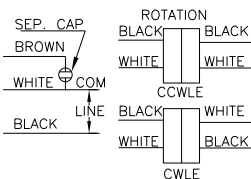

DRAWING REVISION	REVISION BY	DATE
E	MG	26-07-22
ECR-0217450	APPROVED BY	DATE
	LS	26-07-22
ECO DESCRIPTION		
INS CLASS F WAS B, AMB 60/70°C WAS 60°C		

DRAWN BY:
MANOJ

DATE: 16.12.21

APPROVED BY:

DATE: 16.12.21

REFERENCE

THIRD ANGLE PROJECTION



Regal Beloit America, Inc.

DESCRIPTION

MODEL-RFHP-42FR

OUTLINE

MATERIAL

PROCESS/FINISH

SIZE DWG NO

9724_FA

SHEET 1