


PRODUCT INFORMATION PACKET

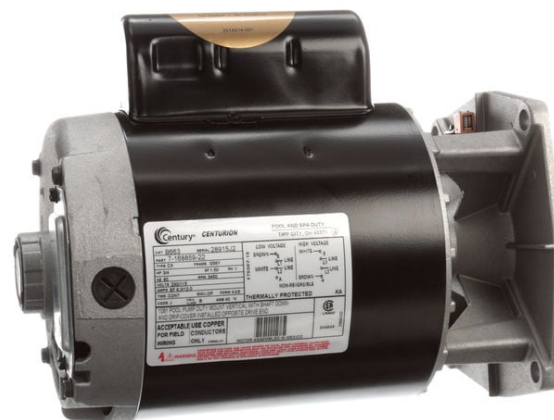

Model No: B663
Catalog No: B663

Pool Pump Motor, 3/4 HP, 1 Ph, 60 Hz, 230/115 V, 3600 RPM, G56Y Frame, DP



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.
©2023 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Output HP	3/4 Hp	Output KW	0.56 kW
Frequency	60 Hz	Voltage	230/115 V
Current	SF 6.0/12.0 A	Speed	3450 rpm
Service Factor	1.5	Phase	1
Duty	Continuous	Insulation Class	B
Frame	G56Y	Enclosure	Drip Proof
Thermal Protection	Thermally Protected	Ambient Temperature	40 °C
UL	Recognized	CSA	Y
Number of Speeds	1		

Technical Specifications

Electrical Type	Permanent Split Capacitor, Single Or Dual Voltage	Poles	2
Rotation	Counterclockwise Pump End	Mounting	Special/Non-Standard
Motor Orientation	Vertical	Drive End Bearing	Ball
Opp Drive End Bearing	Ball	Frame Material	Rolled Steel
Shaft Type	7/16 Threaded	Overall Length	10.89 in
Frame Length	6.00 in	Shaft Diameter	0.625 in
Shaft Extension	1.947 in		
Connection Drawing	17536715.PCX	Outline Drawing	B663-S01

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:01/28/2023



● = CRITICAL DIM



1

13 of 3