

PRODUCT INFORMATION PACKET



Model No: C240
Catalog No: C240

Circulator Pump Motor, 1/2 HP, 1 Ph, 60 Hz, 115/230 V, 1800 RPM, E56Y Frame, DP



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.
©2023 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Phase	1	Output HP	1/2 Hp
Output KW	0.37 kW	Voltage	115/230 V
Speed	1725 rpm	Service Factor	1.25
Frame	E56Y	Enclosure	Drip Proof
Thermal Protection	Thermally Protected	Ambient Temperature	40 °C
Frequency	60 Hz	Current	7.2/3.6 A
Duty	Continuous	Insulation Class	B
UL	Recognized	CSA	Y
CE	N	Number of Speeds	1

Technical Specifications


Electrical Type	Capacitor Start, Induction Run, Single Or Dual Voltage	Starting Method	Across The Line
Poles	4	Rotation	Reversible Clockwise
Mounting	Cushion Ring	Drive End Bearing	Sleeve
Opp Drive End Bearing	Sleeve	Frame Material	Rolled Steel
Shaft Type	Keyed	Overall Length	11.19 in
Frame Length	5.25 in	Shaft Diameter	0.625 in
Shaft Extension	1.94 in		
Outline Drawing	C240	Connection Drawing	17050317.PCX

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/28/2023

C 240

A.O. SMITH CORP. EASTERN MOTOR DIV. TIPP CITY, OHIO.
2 H.P. - 115/230v - 1PH - 60CY - 3450 RPM - TYPE CS
FR. 66 Y - OPEN, B. BRG., MODEL EX 1207

CALIBRATION ON 230 VOLTS.

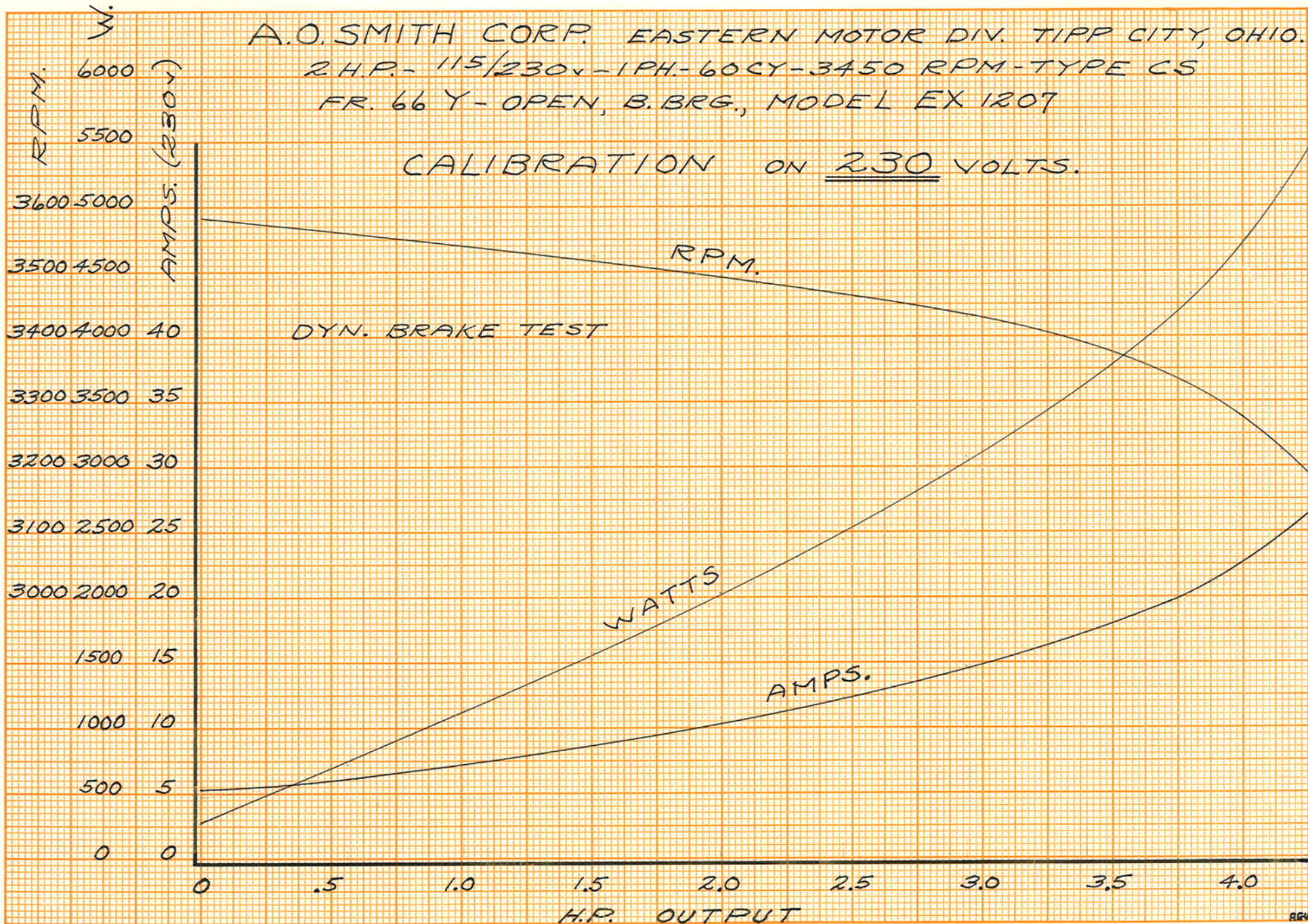

C 240