

PRODUCT INFORMATION PACKET



Model No: C245

Catalog No: C245

Circulator Pump Motor, 1.0 HP, 1 Ph, 60 Hz, 115/230 V, 1800 RPM, L56Y Frame, DP



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications


Output HP	1.0 Hp	Output KW	0.75 kW
Frequency	60 Hz	Voltage	115/230 V
Current	13.0/6.5 A	Speed	1725 rpm
Service Factor	1.25	Phase	1
Duty	Continuous	Insulation Class	B
Frame	L56Y	Enclosure	Drip Proof
Thermal Protection	Thermally Protected	Ambient Temperature	40 °C
UL	Recognized	CSA	Y
CE	N	Number of Speeds	1

Technical Specifications

Electrical Type	Capacitor Start, Induction Run, Single Or Dual Voltage	Starting Method	Across The Line
Poles	4	Rotation	Reversible Clockwise
Mounting	Cushion Ring	Drive End Bearing	Sleeve
Opp Drive End Bearing	Sleeve	Frame Material	Rolled Steel
Shaft Type	Keyed	Overall Length	11.62 in
Frame Length	6.25 in	Shaft Diameter	0.625 in
Shaft Extension	1.37 in		
Connection Drawing	17050317.PCX	Outline Drawing	C245

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/28/2022

C245

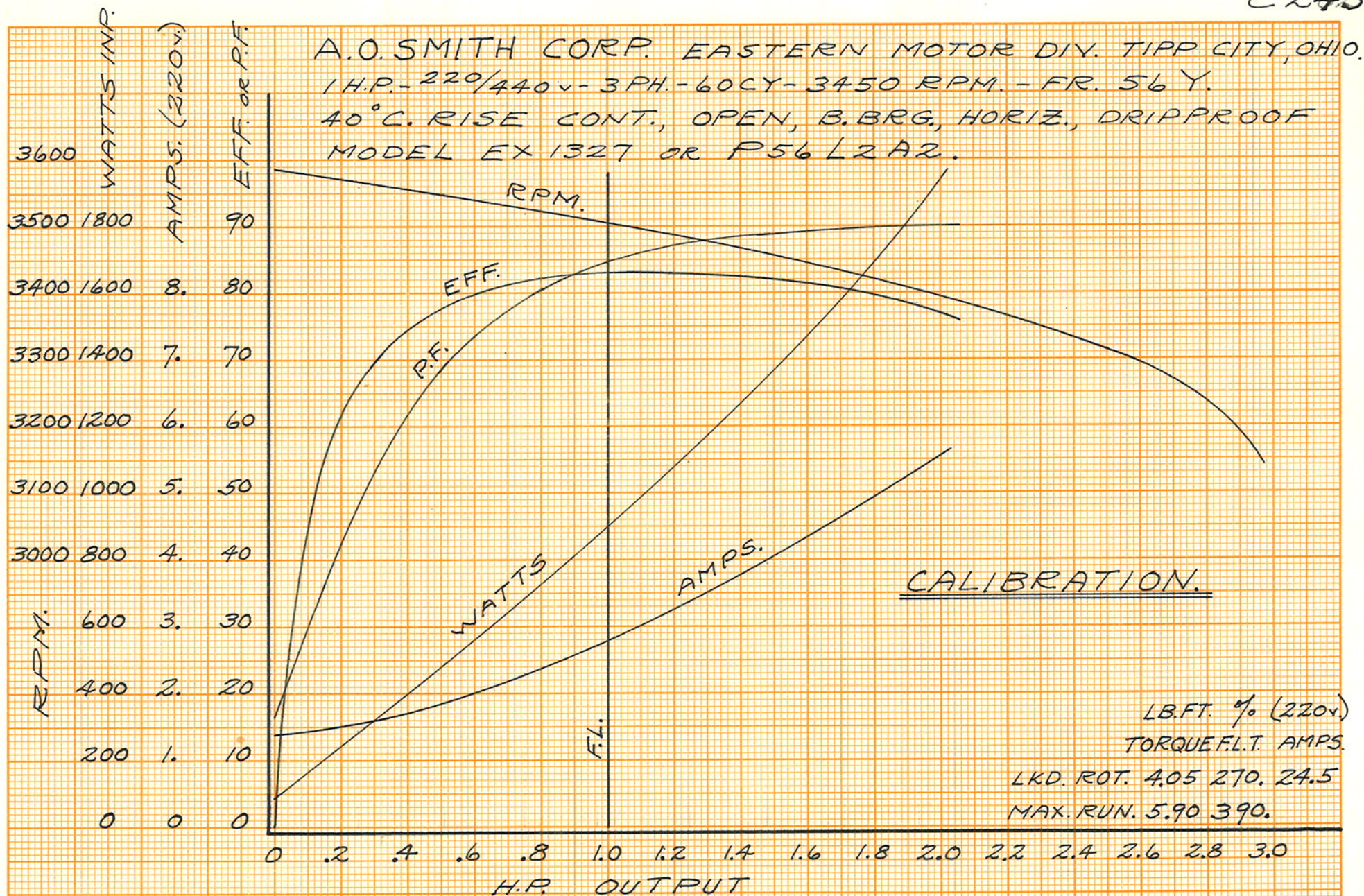

C245