

PRODUCT INFORMATION PACKET



Model No: DBL6406

Catalog No: DBL6406

Fan Coil & Air Conditioner Motor, 1/10,1/15,1/20,1/25 HP, 1 Ph, 60 Hz, 115 V, 1050 RPM, 4 Speed,
42 Frame, OAO



Regal and Century are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications


Output HP	1/10,1/15,1/20,1/25 Hp	Output KW	0.07 kW
Frequency	60 Hz	Voltage	115 V
Current	3.4,2.0,1.7,1.5 A	Speed	1050 rpm
Service Factor	1	Phase	1
Duty	Air Over	Insulation Class	B
Frame	42Y	Enclosure	Open Air Over
Thermal Protection	Automatic	Ambient Temperature	40 °C
UL	Recognized	CSA	Y
CE	N	Number of Speeds	4

Technical Specifications

Electrical Type	Shaded Pole	Starting Method	Across The Line
Poles	6	Rotation	Counterclockwise Lead End
Mounting	Resilient Base	Motor Orientation	Horizontal
Drive End Bearing	Sleeve	Opp Drive End Bearing	Sleeve
Frame Material	Rolled Steel	Shaft Type	Flat
Overall Length	24.00 in	Shaft Diameter	0.500 in
Shaft Extension	10.3X.5X10.3 in		
Connection Drawing	263B806F02	Outline Drawing	11927-016-S01

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/28/2022

SHEET	1
-------	---

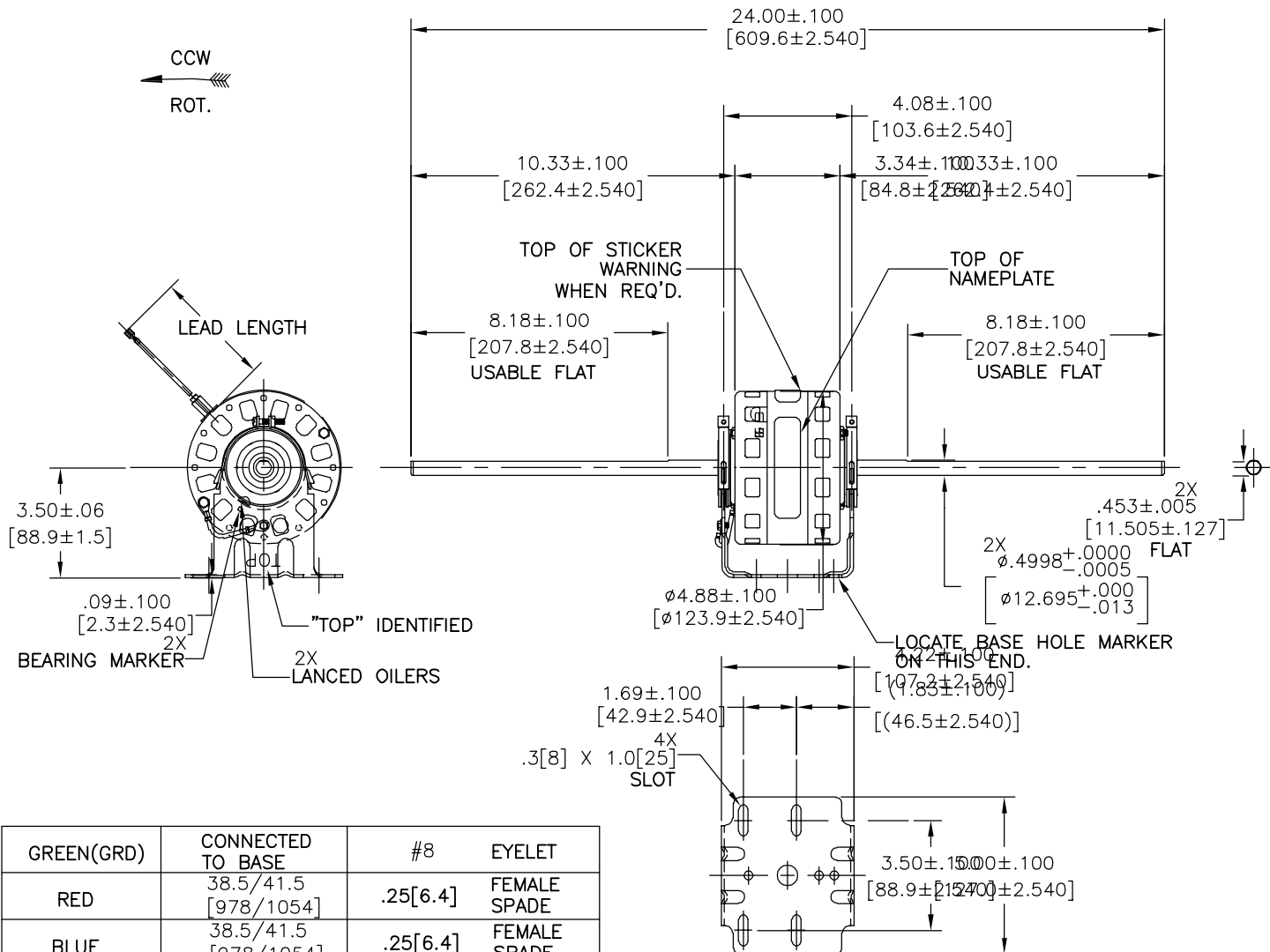

GREEN(GRD)	CONNECTED TO BASE	#8	EYELET
RED	38.5/41.5 [978/1054]	.25[6.4]	FEMALE SPADE
BLUE	38.5/41.5 [978/1054]	.25[6.4]	FEMALE SPADE
YELLOW	38.5/41.5 [978/1054]	.25[6.4]	FEMALE SPADE
BLACK	38.5/41.5 [978/1054]	.25[6.4]	FEMALE SPADE
WHITE	38.5/41.5 [978/1054]	.25[6.4]	FEMALE SPADE
COLOR	LENGTH	TERMINAL OR STRIP LENGTH	

MAIN FRAME – OLE	OPEN
END FRAME – OLE	OPEN
MAIN FRAME – LE	OPEN
END FRAME – LE	OPEN

CUSTOMER	DISTRIBUTION SERVICES
----------	-----------------------

AND ITS INFORMATION ARE
NTIAL PROPERTY OF REGAL
ARE NOT TO BE DISCLOSED,
OTHERWISE USED WITHOUT
EGAL-BELOIT CORPORATION.

SHEET	1
-------	---

ASME Y14.5M 1994

DIMENSIONS WITHOUT TOLERANCES ARE
FOR REFERENCE ONLY.

AND ITS INFORMATION ARE
NTIAL PROPERTY OF REGAL
ARE NOT TO BE DISCLOSED,
OTHERWISE USED WITHOUT
EGAL-BELOIT CORPORATION.

SHEET	1
-------	---

[illegible]