


PRODUCT INFORMATION PACKET

FASCO®

Model No: D1048

Catalog No: D1048

OEM Replacement Motor, 1/20 HP, 1 Ph, 60 Hz, 277 V, 1075 RPM, 3 Speed, 42 Frame, OAO

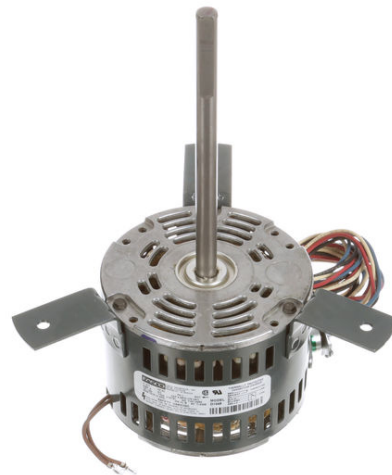

Regal and Fasco are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E

RegalRexnord



Nameplate Specifications

| | | | |
|--------------------|------------|---------------------|---------------|
| Output HP | 1/20 Hp | Output KW | 0.04 kW |
| Frequency | 60 Hz | Voltage | 277 V |
| Current | 0.5 A | Speed | 1075 rpm |
| Service Factor | 1 | Phase | 1 |
| Duty | Continuous | Insulation Class | B |
| Frame | 42 | Enclosure | Open Air Over |
| Thermal Protection | Automatic | Ambient Temperature | 40 °C |
| UL | Recognized | CSA | Y |
| CE | N | Number of Speeds | 3 |

Technical Specifications

| | | | |
|-----------------------|---------------------------|--------------------|---------------------|
| Electrical Type | Permanent Split Capacitor | Starting Method | Across The Line |
| Poles | 6 | Rotation | Clockwise Shaft End |
| Mounting | Lug | Drive End Bearing | Sleeve |
| Opp Drive End Bearing | Sleeve | Frame Material | Rolled Steel |
| Shaft Type | Flat | Overall Length | 11.12 in |
| Frame Length | 3.38 in | Shaft Diameter | 0.500 in |
| Shaft Extension | 7.25 in | | |
| Outline Drawing | 7187025002_S001 | Connection Drawing | SEE OUTLINE |

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/29/2022