


PRODUCT INFORMATION PACKET

Model No: D1081

Catalog No: D1081

OEM Replacement Motor, 1/6-1/8-1/10 HP, 1 Ph, 60 Hz, 115 V, 1625 RPM, 3 Speed, 42 Frame, OAO

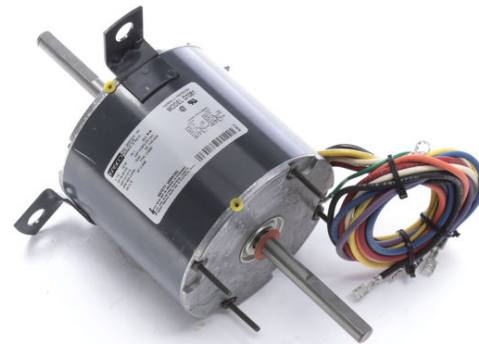

Regal and are trademarks of Regal Rexnord Corporation or one of its affiliated companies.
©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E

Nameplate Specifications

Output HP	1/6-1/8-1/10 Hp	Output KW	0.13 kW
Frequency	60 Hz	Voltage	115 V
Current	2.4-1.9-1.5 A	Speed	1625 rpm
Service Factor	1	Phase	1
Duty	Continuous	Insulation Class	B
Frame	42	Enclosure	Open Air Over
Thermal Protection	Automatic	Ambient Temperature	40 °C
UL	Recognized	CSA	Y
CE	N	Number of Speeds	3

Technical Specifications

Electrical Type	Permanent Split Capacitor	Starting Method	Across The Line
Poles	4	Rotation	Reversible
Mounting	Lug	Drive End Bearing	Sleeve
Opp Drive End Bearing	Sleeve	Frame Material	Rolled Steel
Shaft Type	Flat	Overall Length	12.05 in
Frame Length	4.38 in	Shaft Diameter	0.500 in
Shaft Extension	3.5 in		
Outline Drawing	7185000807_S001	Connection Drawing	SEE OUTLINE

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:09/15/2022