


PRODUCT INFORMATION PACKET

FASCO®

Model No: D1164

Catalog No: D1164

OEM Replacement Motor, 1/25 HP, 1 Ph, 60 Hz, 115/230 V, 1550 RPM, 1 Speed, 3.3" Diameter, TEFC

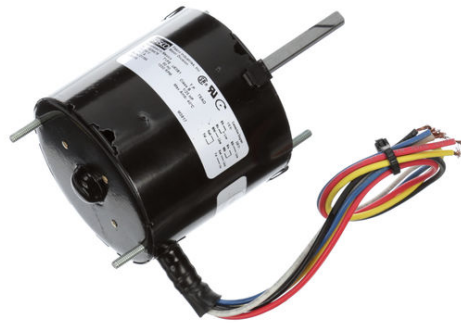

Regal and Fasco are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

©2022 Regal Rexnord Corporation, All Rights Reserved. MC017097E

RegalRexnord



Nameplate Specifications

Output HP	1/25 Hp	Output KW	0.03 kW
Frequency	60 Hz	Voltage	115/230 V
Current	1.30/0.70 A	Speed	1550 rpm
Service Factor	1	Phase	1
Efficiency	35 %	Duty	Air Over
Insulation Class	B	Frame	3.3
Enclosure	Totally Enclosed Fan Cooled	Thermal Protection	Thermally Protected
Ambient Temperature	40 °C	UL	Recognized
CSA	Y	CE	N
Number of Speeds	1		

Technical Specifications

Electrical Type	Shaded Pole	Starting Method	Across The Line
Poles	4	Rotation	Clockwise Shaft End
Mounting	Extended Studs	Drive End Bearing	Sleeve
Opp Drive End Bearing	Sleeve	Frame Material	Steel
Shaft Type	Flat	Overall Length	6.00 in
Frame Length	2.95 in	Shaft Diameter	0.313 in
Shaft Extension	2.5 in		
Outline Drawing	71636478	Connection Drawing	SEE OUTLINE

This is an uncontrolled document once printed or downloaded and is subject to change without notice. Date Created:11/29/2022